

Relief Valves




Balanced Piston Type Relief Valves

(F3)CS-H10-*(V)-30

● Available in lot kits of 25 pieces

Model	■ Spring	Pressure Range PSI	■ Included in Cover S/A
C*-H10-BV-30	2280	125-1000	941286
C*-H10-CV-30	583937	500-2000	941287
C*-H10-FY-30	2281	1500-3000	941288

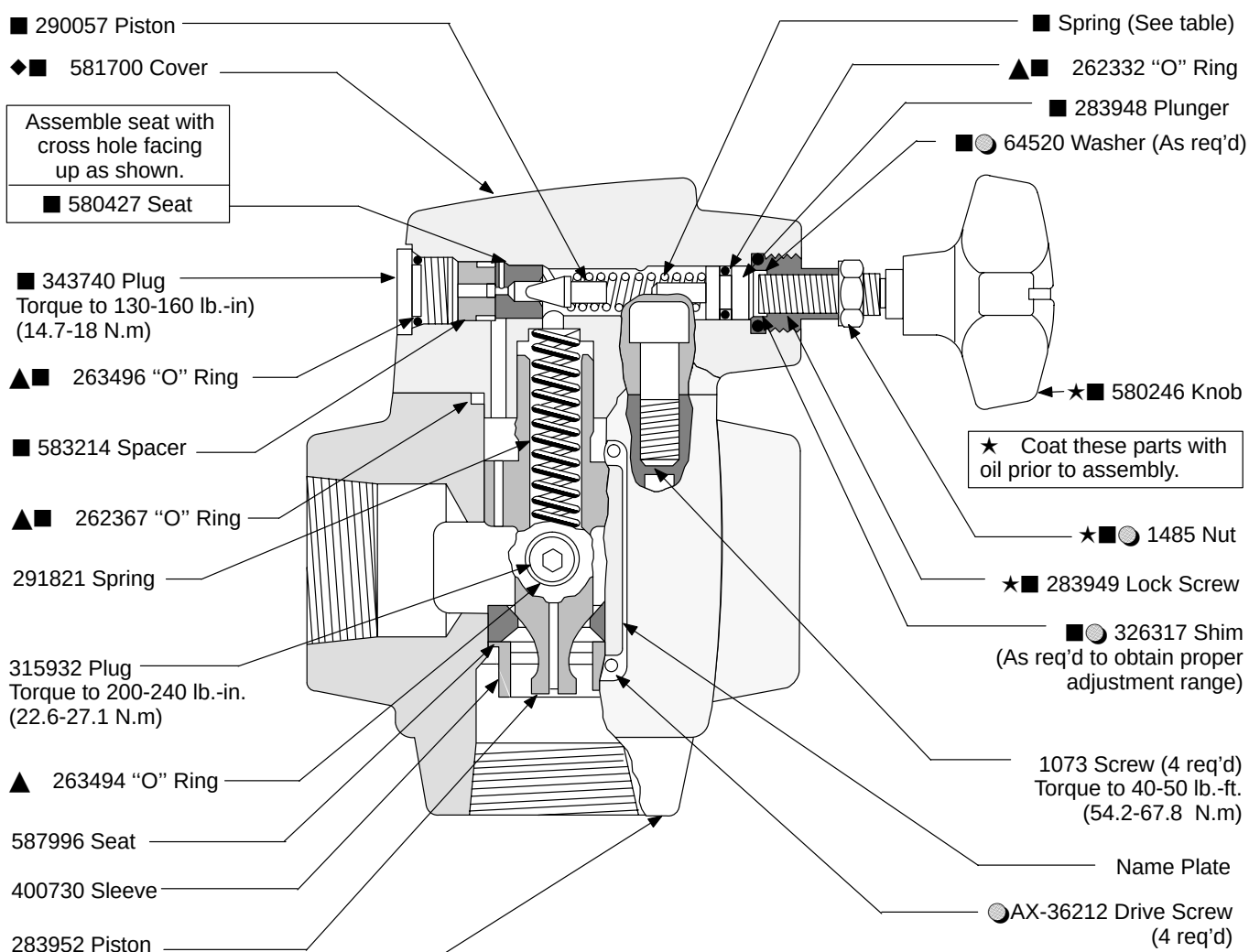


Model	◆ Body
CS-H10-*(V)-30	580430

◆ Not available for sale.

▲ Included in F3 Seal Kit 920225

Model Code Breakdown

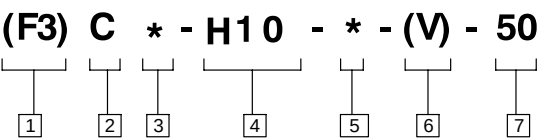

1 Seals

F3 - Multi-fluid capability (Viton® seals)

Viton is a registered trademark of E.I. DuPont

2 Model Series

C - Relief valve

3 Threads

S - SAE straight

4 Size

H10 - 1-1/4 inch high flow

5 Pressure Range

B - 125-1000

C - 500-2000

F - 1500-3000

6 Vent Pressure

V - High vent pressure

7 Design

For satisfactory service life of these components, use full flow filtration to provide fluid which meets ISO cleanliness code 18/15 or cleaner. Selections from Eaton OFF, OFR and OFRS filter series are recommended.

Printed in U.S.A.