


Relief Valves



High Flow Relief Valve Module

(F3) DGC-H06-*(*)-60

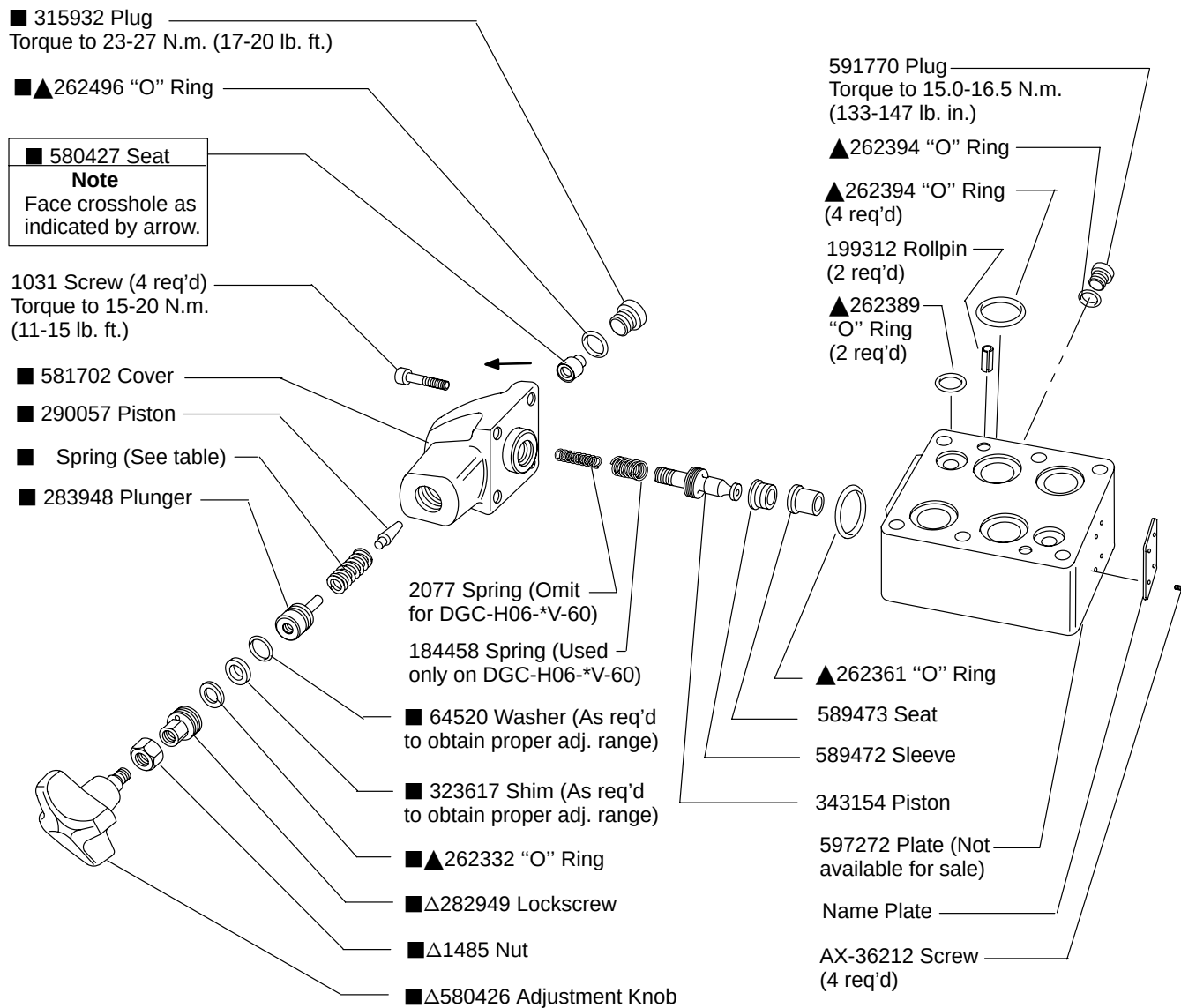

▲ Service all units w/F3 Seal Kit 919655


△ Coat with oil prior to assembly.

CAUTION

This model cannot be used with pressure centered (D) valves.

Model	■ Included in Cover S/A	■ Spring
DGC-H06-B*-60	941280	2280
DGC-H06-C*-60	941281	583937
DGC-H06-F*-60	941282	2281

Model Code

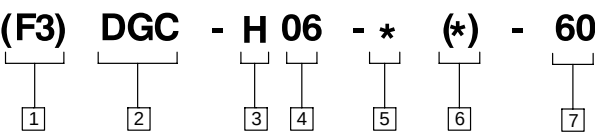

1Seals F3 - Seals for mineral oil and fire resistant fluids	4Size 06 - 3/4 inch	6Vent Spring V - High vent spring (Omit for low vent models)
2Model Series DGC - Directional control, subplate mounted relief module	5Pressure Range B - 125-1000 psi C - 500-2000 psi F - 1500-3000 psi	7Design
3High Flow H - 70 USgpm		

For satisfactory service life of these components, use full flow filtration to provide fluid which meets ISO cleanliness code 18/15 or cleaner. Selections from Eaton OFP,OFR and OFRS filter series are recommended.

Printed in U.S.A.