

# Weatherproof receptacle covers

## Weatherproof covers for locking and straight blade receptacles


### Product description

Nylon covers for FS/FD boxes

### Weatherproof nylon covers for 15A, 20A & 30A devices

#### Features

- UL Listed for wet locations (cover closed) and damp locations (cover open or closed)
- Meets 2014 NEC® 406.9 (A) and 406.9 (B)(2)
- Rugged, glass-filled nylon provides high strength and wide temperature range for long life in abusive environments
- Easy mounting on FS/FD boxes or equipment panels
- Self-closing lift lid cover with neoprene gasket and stainless steel spring provides weather-proof protection
- Universal mounting holes to accept all Eaton's 15 & 20A and 30A locking flanged inlets and outlets, receptacles as well as devices with similar dimensions from other manufacturers

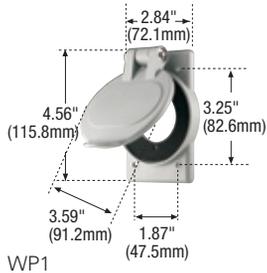

WP1



WP2

### Glass-filled nylon covers

Description	Mtg. hole pattern	Color	Opening diameter	Catalog no.		
For 15 & 20A straight blade receptacles and 15A flanged inlets & outlets	2 holes 180°, 2.09" (53.1mm) bolt dia. circle	GY	1.75" (44.45mm)	□ WP1*	•	•
For 20 & 30A flanged inlets & outlets and 30 & 50A, 3-W straight blade receptacles	Two sets of 3 equally spaced holes: 3 holes on 2.5" (63.5mm) bolt dia. circle and 3 holes on 2.69" (68.3mm) bolt dia. circle	GY	2.25" (57.15mm)	□ WP2	•	•

\* Not CSA certified

## Metal weatherbox while-in-use weather protective covers


### Product description

Metal 1-Gang lockable cover boxes

### Metal while-in-use cover boxes

#### Features

- Meets 2014 NEC® 406.9 (B)(1) for receptacles in damp or wet locations for one or two family dwellings
- Diecast powder coated aluminum
- NEMA Type 3R rating
- Comes with gasket, mounting hardware, duplex receptacle insert and GFCI receptacle insert
- Lockable to prevent accidental disconnects

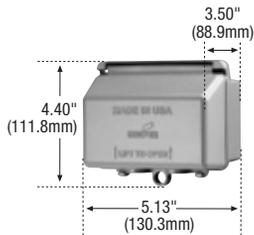

WIUMH-1



WIUM inserts

### Metal protective covers

Description	# of available config. using inserts	Color	Depth	Catalog no.		
Vertical mount	2	GY	3.25" deep (82.6mm)	□ WIUMV-1	•	•
Horizontal mount	2	GY	3.25" deep (82.6mm)	□ WIUMH-1	•	•

### Extra duty metal while-in-use protective covers

Description	# of available config. using inserts	Color	Depth	Catalog no.	
Vertical mount	2	GY	3.25" deep (82.6mm)	□ WIUMV-1X	•
Horizontal mount	2	GY	3.25" deep (82.6mm)	□ WIUMH-1X	•

### Color information:

GY (Gray)



(Gray)

Compliances, specifications and availability are subject to change without notice.

 Indicates NAFTA compliant - Page Q-32

 RoHS compliant - Page Q-32