


Surge protection devices

Surge protection adapters

Product description

2-pole, 3-wire grounding
 15A, 125V/AC
 Plug-In, NEMA 5-15R
 Type 3 SPD

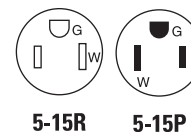

1177CG

Six outlet surge adapters – plug-in

Features

- Provides full three mode surge protection for hot to neutral, hot to ground and neutral to ground (except 1156CG)
- Center mounting screw provided for permanent attachment to receptacle
- EMI/RFI filtering minimizes line noise
- Made of high impact-resistant thermoplastic for long-term durability
- Telephone/fax/modem protection provided with RJ11-type telephone ports (4-wire protection)
- \$5,000 connected equipment warranty on 1162CG and 1177CG
- \$2,500 connected equipment warranty on 1156CG
- Type 3 SPD



1176

Six outlet surge adapters – plug-in



Rating A	V/AC	Joules	Max surge current	Description	Color	Catalog no.
15	125	340	12kA/mode	Full protection	CG	<input type="checkbox"/> 1177CG
		340	12kA/mode	Full protection w/ telephone jacks	CG	<input type="checkbox"/> 1162CG
		170	12kA/mode	Basic protection	CG	<input type="checkbox"/> 1156CG

Surge protection power strip

Features

- Portable strip provides 7 surge-protected outlets anywhere for stereos, TVs, computers or other electronic-based equipment
- Full mode surge protection for hot to neutral, hot to ground and neutral to ground
- Resettable 15 amp circuit breaker
- Made of high impact-resistant thermoplastic for long-term durability
- Comes complete with 14/3 SJT 4' (1.22m) portable cord
- Pilot light on/off switch indicates power to unit


Surge bloc surge protection receptacles w/audible alarm



Rating A	V/AC	Joules	Description	Color	Catalog no.
15	125	70J	Full protection 7 outlet with circuit breaker	V	<input type="checkbox"/> 1176V

Color information:

 CG (Computer Gray), V (Ivory)



Compliances, specifications and availability are subject to change without notice.