

## GFCI & surge protection receptacles

### Hospital grade self-test GFCI receptacles

#### Product description


2-pole, 3-wire grounding  
15A, 125V/AC; 20A, 125V/AC  
NEMA 5-15R, 5-20R




5-15R




5-20R

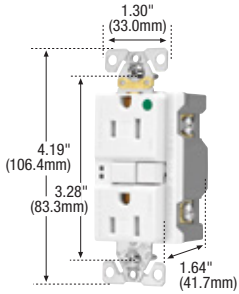


TRSGFH15

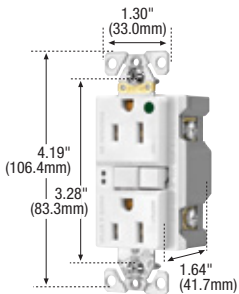

SGFH15

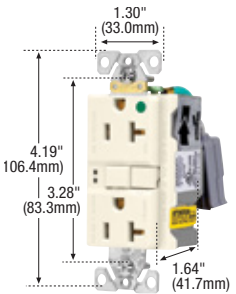

SGFH20\_MOD

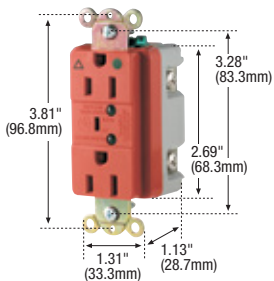

IG8200HG\_S

#### Premium hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH15__		•	•		
			Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH15F__		•	•	•	•
			Tamper resistant hospital GFCI, back & side wire	B, BK, GY, LA, RD, V, W	□ TRSGFH15__		•	•		
			Tamper resistant hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ TRSGFH15F__		•	•	•	•
20	125	5-20R	Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH20__		•	•		
			Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH20F__		•	•	•	•
			Tamper resistant hospital GFCI, back & side wire	B, BK, GY, LA, RD, V, W	□ TRSGFH20__		•	•		
			Tamper resistant hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ TRSGFH20F__		•	•	•	•

Includes standard size unbreakable wallplate

### Hospital grade surge protection receptacles with LED indicators & audible alarm

#### Product description

2-pole, 3-wire grounding  
15A, 125V/AC  
20A, 125V/AC  
NEMA 5-15R, 5-20R



5-15R



5-20R

#### Surge protection receptacles w/audible alarm & LED indicators



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Hospital grade duplex receptacle, back & side wire	BL, RD, V, W	□ 8200__S		•	•		
			IG hospital grade duplex receptacle, back & side wire	BL, RN, V, W	□ IG8200HG__S		•	•		
20	125	5-20R	Hospital grade duplex receptacle, back & side wire	BL, RD, V, W	□ 8300__S		•	•		
			IG hospital grade duplex receptacle, back & side wire	BL, RN, V, W	□ IG8300HG__S		•	•		

560 Joules, max. surge current - 18kA, MCOV - 150V/AC

#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)



#### Specification information:

Hospital grade GFCI: H-9  
Surge protection receptacles with audible alarm & LED: I-20

#### Compliances, specifications and availability are subject to change without notice.

➡ ArrowLink option available. Add "MOD" suffix to standard catalog number (example TRSGFH15W, TRSGFH15WMOD). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page J-9

Tamper resistant

Build-to-spec customizable devices - Page J-10

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32