 


Eaton Wiring Devices


Wallplate selector guide

Toggle




#-Gang	Standard Size				Mid-Size				Oversize	
	Thermoset	Nylon	Stainless Steel	Brass	Thermoset	Polycarbonate	Screwless	Stainless Steel	Thermoset	Stainless Steel
1-Gang	2134__	5134__	93071	94071	2034__	PJ1__	PJS1__	93971	2144__	93871
2-Gang	2139__	5139__	93072	94072	2039__	PJ2__	PJS2__	93972	2149__	93872
3-Gang	2141__	5141__	93073	94073	2041__	PJ3__	PJS3__	93973	2741__	93873
4-Gang	2154__	5154__	93074	–	2054__	PJ4__	PJS4__	–	–	93874
5-Gang	2155__	–	93075	–	–	PJ5__	–	–	–	–
6-Gang	2156__	–	93076	–	–	PJ6__	–	–	–	–

 Decorator/GFCI




#-Gang	Standard Size				Mid-Size				Oversize	
	Thermoset	Nylon	Stainless Steel	Brass	Thermoset	Polycarbonate	Screwless	Stainless Steel	Thermoset	Stainless Steel
1-Gang	2151__	5151__	93401	94401	2051__	PJ26__	PJS26__	93934	2751__	93834
2-Gang	2152__	5152__	93402	94402	2052__	PJ262__	PJS262__	93935	–	–
3-Gang	2163__	–	93403	–	2063__	PJ263__	PJS263__	93936	–	–
4-Gang	2164__	–	93404	–	2064__	PJ264__	PJS264__	–	–	–
5-Gang	2165__	–	93405	–	–	PJ265__	PJS265__	–	–	–
6-Gang	2166__	–	93406	–	–	PJ266__	PJS266__	–	–	–

 Duplex Receptacle



#-Gang	Standard Size				Mid-Size				Oversize	
	Thermoset	Nylon	Stainless Steel	Brass	Thermoset	Polycarbonate	Screwless	Stainless Steel	Thermoset	Stainless Steel
1-Gang	2132__	5132__	93101	94101	2032__	PJ8__	PJS8__	93901	2142__	93801
2-Gang	2150__	5150__	93102	94102	2050__	PJ82__	–	93902	2750__	93802
3-Gang	–	–	93103	–	–	–	–	–	–	–

 Blank



#-Gang	Standard Size				Mid-Size				Oversize	
	Thermoset	Nylon	Stainless Steel	Brass	Thermoset	Polycarbonate	Screwless	Stainless Steel	Thermoset	Stainless Steel
1-Gang	2129__	5129__	93151	94151	2029__	PJ13__	–	93951	2729__	93851
2-Gang	2137__	5137__	93152	–	2037__	PJ23__	–	–	–	93852
3-Gang	–	–	93153	–	–	–	–	–	–	–
4-Gang	–	–	93154	–	–	–	–	–	–	–
1-Strap mt.	–	–	–	–	–	PJ14__	–	–	–	–

 


Powering Business Worldwide

Eaton Wiring Devices


Wallplate selector guide

Power Outlet




Hole dia.	Standard Size					Mid-Size				Oversize	
	Thermoset	Nylon	Stainless Steel	Brass	Chrome	Thermoset	Nylon	Polycarbonate	Stainless Steel	Thermoset	Stainless Steel
1-1.40" hole	2131__	5131__	93091	-	-	-	-	PJ7__	-	2731__	93891
1-1.59" hole	-	-	93111	-	-	-	-	PJ720__	-	-	-
1-2.15" hole	-	-	93221	-	39CH	2068__	5068__	PJ724__	-	-	-
2-2.15" hole	2168__	-	93227	-	68	-	-	PJ703__	-	-	-

 Combination



2-Gang and 3-Gang	Standard Size				Mid-Size			Oversize
	Thermoset	Nylon	Stainless Steel	Brass	Thermoset	Polycarbonate	Stainless Steel	Thermoset
Toggle & duplex receptacle	2138__	5138__	93532	94532	2038__	PJ18__	93932	2148__
Toggle & single receptacle	-	-	-	-	-	-	-	-
Toggle & decorator	2153__	5153__	93432	94432	2053__	PJ126__	93937	-
Toggle & blank	-	5171__	-	-	-	PJ113__	-	-
Duplex receptacle & blank	-	5170__	-	-	-	PJ138__	-	-
Duplex receptacle & decorator	2157__	-	-	-	-	PJ826__	-	-
2 Toggles & duplex receptacle	2158__	5158__	93543	-	-	PJ28__	-	-
2 Toggles & decorator	2173__	-	93443	-	-	PJ226__	-	-


 
Screwless Decorator



#-Gang	Mid-Size	#-Gang	Mid-Size
	Polycarbonate		Polycarbonate
1-Gang	PJS26__	4-Gang	PJS264__
2-Gang	PJS262__	5-Gang	PJS265__
3-Gang	PJS263__	6-Gang	PJS266__

Color ordering information:

B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RN (Orange), RD (Red), V (Ivory), W (White), Stainless Steel, BB (Brushed Bronze), Brass, RB (Oil Rubbed Bronze), SG (Silver Granite)

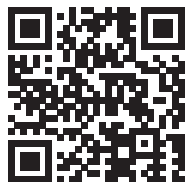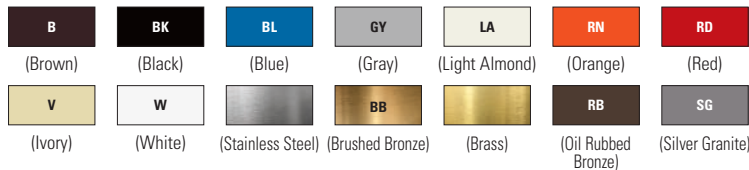

For more information on color availability and wallplate sizes, refer to Section P in the digital buyers guide at Eaton.com/wdbuyersguide

Size Options:

